



Coloane
luminoase Ø50
mm
LTN50

Denumirea produsului

Denumirea tipului de produs

Caracteristici generale

Diametru mm - inch 50 / 1.97

Material Metal

Caracteristici mecanice

Greutate g 27


Conditii ambientale

Temperatura

Temperatura de Operare

min °C -30
max °C +50

Dimensiuni

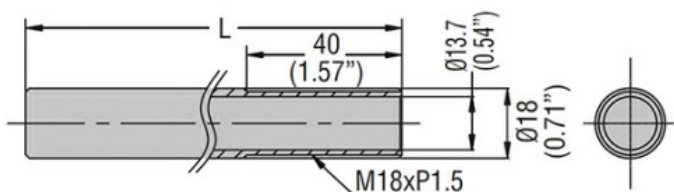

Type	L (mm/in)
LTP50P050T	50 (1.97")
LTP50P100T	100 (3.94")
LTP50P250T	250 (9.84")
LTP50P400T	400 (15.75")

Certificari si conformitate

Conformitate

CSA C22.2 n° 14
IEC/EN/BS 60947-1
IEC/EN/BS 60947-5-1
UL508

Certificate

cULus

Clasificare ETIM

ETIM 8.0

EC001155 - Tub
pentru coloana
de semnal