



Denumirea produsului Coloane luminoase Ø50 mm  
Denumirea tipului de produs LTN50

**Caracteristici generale**

Diametru mm - inch 50 / 1.97  
Material Metal


**Caracteristici mecanice**

Greutate g 66

**Conditii ambientale**

Temperatura  
Temperatura de Operare  
min °C -30  
max °C +50

**Dimensiuni**

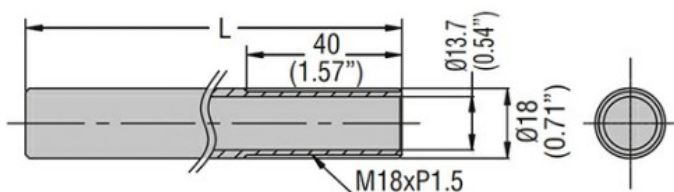

Type	L (mm/in)
LTP50P050T	50 (1.97")
LTP50P100T	100 (3.94")
LTP50P250T	250 (9.84")
LTP50P400T	400 (15.75")

**Certificari si conformitate**

Conformitate  
CSA C22.2 n° 14  
IEC/EN/BS 60947-1  
IEC/EN/BS 60947-5-1  
UL508

Certificate  
cULus

**Clasificare ETIM**

ETIM 8.0 EC001155 - Tub pentru coloana de semnal