



Denumirea produsului

Coloane
iluminate Ø70
mm
LTN70

Denumirea tipului de produs

Caracteristici generale

Diametru	mm - inch	70 / 2.75
Culoare		Portocaliu
grad de protectie IEC		IP65
Consumul de energie	VA	1.2

Caracteristici mecanice

Greutate	g	66
----------	---	----


Conditii ambientale

Temperatura

Temperatura de Operare

min	°C	-30
max	°C	+50

Dimensiuni

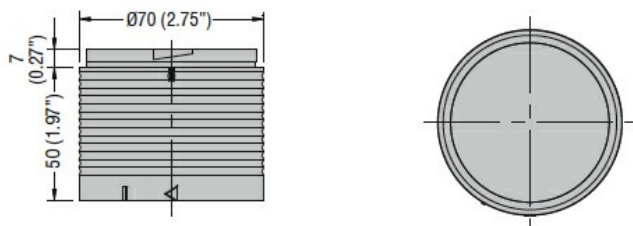

Certificari si conformitate

Conformitate

CSA C22.2 n° 14
IEC/EN/BS 60947-1
IEC/EN/BS 60947-5-1
UL508

Certificate

cULus

Clasificare ETIM

ETIM 8.0

EC000232 -
Modul optic
pentru turn de
semnalizare