



Denumirea produsului	Coloane iluminate Ø70 mm
Denumirea tipului de produs	LTN70

#### Caracteristici generale

Diametru	mm - inch	70 / 2.75
Culoare		Roșu
grad de protectie IEC		IP65
Consumul de energie	VA	1.2


#### Caracteristici mecanice

Greutate	g	66
----------	---	----

#### Conditii ambientale

Temperatura	Temperatura de Operare			
		min	°C	-30
		max	°C	+50

#### Dimensiuni

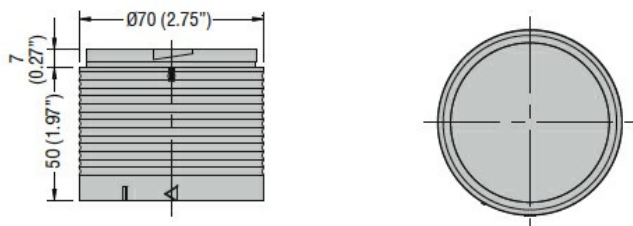

#### Certificari si conformitate

Conformitate	CSA C22.2 n° 14
	IEC/EN/BS 60947-1
	IEC/EN/BS 60947-5-1
	UL508

Certificate	cULus
-------------	-------

#### Clasificare ETIM

ETIM 8.0	EC000232 - Modul optic pentru turn de semnalizare
----------	---