



Denumirea produsului
Denumirea tipului de produs

Coloane iluminate Ø70 mm
LTN70

Caracteristici generale

| | | |
|-----------------------|-----------|-----------|
| Diametru | mm - inch | 70 / 2.75 |
| Culoare | | alb |
| grad de protectie IEC | | IP65 |
| Consumul de energie | VA | 1.2 |


Caracteristici mecanice

| | | |
|----------|---|----|
| Greutate | g | 66 |
|----------|---|----|

Conditii ambientale

| | | | | |
|-------------|------------------------|-----|----|-----|
| Temperatura | Temperatura de Operare | | | |
| | | min | °C | -30 |
| | | max | °C | +50 |

Dimensiuni

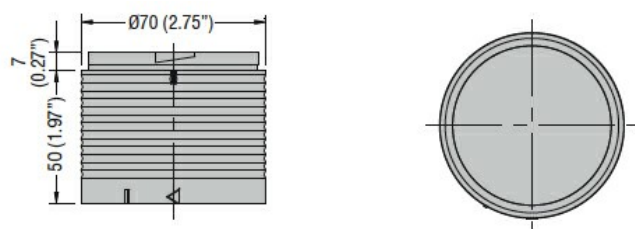

Certificari si conformitate

| | |
|--------------|---------------------|
| Conformitate | CSA C22.2 n° 14 |
| | IEC/EN/BS 60947-1 |
| | IEC/EN/BS 60947-5-1 |
| | UL508 |

| | |
|-------------|-------|
| Certificate | cULus |
|-------------|-------|

Clasificare ETIM

| | |
|----------|---|
| ETIM 8.0 | EC000232 - Modul optic pentru turn de semnalizare |
|----------|---|