



Denumirea produsului

Coloane
 iluminate Ø70
 mm
 LTN70

Denumirea tipului de produs

Caracteristici generale

Diametru	mm - inch	70 / 2.75
grad de protectie IEC		IP20
Consumul de energie	VA	1.7
Intensitatea sunetului	dB	100

Caracteristici mecanice

Greutate	g	62
----------	---	----


Conditii ambientale

Temperatura

Temperatura de Operare

min	°C	-30
max	°C	+50

Dimensiuni

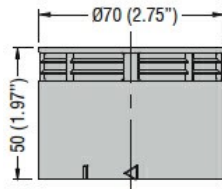

Certificari si conformitate

Conformitate

CSA C22.2 n° 14
 IEC/EN/BS 60947-1
 IEC/EN/BS 60947-5-1
 UL508

Certificate

cULus

Clasificare ETIM

ETIM 8.0

EC001261 -
 Element acustic
 pentru coloana
 de semnal