



Denumirea produsului	Coloane iluminate Ø70 mm
Denumirea tipului de produs	LTN70

Caracteristici generale

Diametru	mm - inch	70 / 2.75
grad de protectie IEC		IP65
Consumul de energie	VA	1.7
Intensitatea sunetului	dB	85


Caracteristici mecanice

Greutate	g	65
----------	---	----

Conditii ambientale

Temperatura	Temperatura de Operare			
		min	°C	-30
		max	°C	+50

Dimensiuni

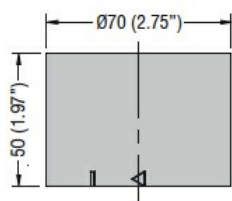

Certificari si conformitate

Conformitate	CSA C22.2 n° 14
	IEC/EN/BS 60947-1
	IEC/EN/BS 60947-5-1
	UL508

Certificate	cULus
-------------	-------

Clasificare ETIM

ETIM 8.0	EC001261 - Element acustic pentru coloana de semnal
----------	--