



Coloane
iluminate Ø70
mm
LTN70

Denumirea produsului

Denumirea tipului de produs

Caracteristici generale

Diametru mm - inch 70 / 2.75

Material Metal

Caracteristici mecanice

Greutate g 39


Conditii ambientale

Temperatura

Temperatura de Operare

min °C -30
max °C +50

Dimensiuni

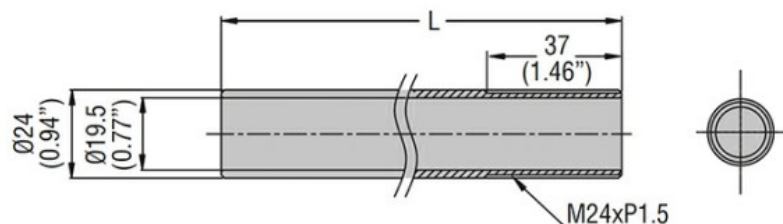

| Type | L (mm/in) |
|------------|--------------|
| LTP70P050T | 50 (1.97") |
| LTP70P100T | 100 (3.94") |
| LTP70P250T | 250 (9.84") |
| LTP70P400T | 400 (15.75") |

Certificari si conformitate

Conformitate

CSA C22.2 n° 14
IEC/EN/BS 60947-1
IEC/EN/BS 60947-5-1
UL508

Certificate

cULus

Clasificare ETIM

ETIM 8.0

EC001155 - Tub
pentru coloana
de semnal