



Denumirea produsului

Coloane
iluminate Ø70
mm
LTN70

Denumirea tipului de produs

Caracteristici generale

Diametru mm - inch 70 / 2.75

Material Metal

Caracteristici mecanice

Greutate g 100


Conditii ambientale

Temperatura

Temperatura de Operare

min °C -30
max °C +50

Dimensiuni

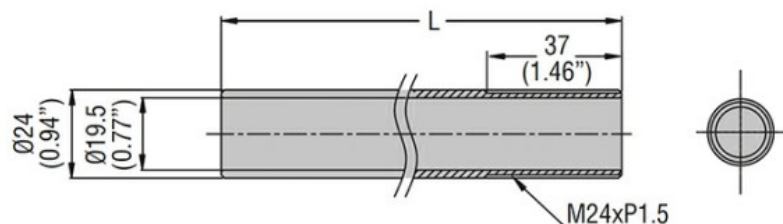

Type	L (mm/in)
LTP70P050T	50 (1.97")
LTP70P100T	100 (3.94")
LTP70P250T	250 (9.84")
LTP70P400T	400 (15.75")

Certificari si conformitate

Conformitate

CSA C22.2 n° 14
IEC/EN/BS 60947-1
IEC/EN/BS 60947-5-1
UL508

Certificate

cULus

Clasificare ETIM

ETIM 8.0

EC001155 - Tub
pentru coloana
de semnal