



Denumirea produsului

Coloane  
iluminate Ø70  
mm  
LTN70

Denumirea tipului de produs

**Caracteristici generale**

Diametru mm - inch 70 / 2.75

Material Metal

**Caracteristici mecanice**

Greutate g 167


**Conditii ambientale**

Temperatura

Temperatura de Operare

min °C -30  
max °C +50

**Dimensiuni**

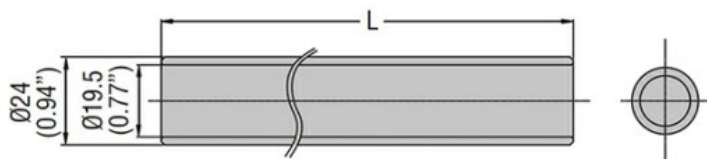

| Type      | L (mm/in)    |
|-----------|--------------|
| LTP70P050 | 50 (1.97")   |
| LTP70P100 | 100 (3.94")  |
| LTP70P250 | 250 (9.84")  |
| LTP70P400 | 400 (15.75") |

**Certificari si conformitate**

Conformitate

CSA C22.2 n° 14  
IEC/EN/BS 60947-1  
IEC/EN/BS 60947-5-1  
UL508

Certificate

cULus

**Clasificare ETIM**

ETIM 8.0

EC001155 - Tub  
pentru coloana  
de semnal