





Number of poles	Nr.	3
Operating voltage type		AC
<b>Contact characteristics</b>		
IEC Conventional free air thermal current I <sub>th</sub>	A	40
Rated short time current (1s) I <sub>cw</sub> (rms)	kA	0.8
<b>Mechanical features</b>		
Tightening torque for terminals	min	Nm 1.8
	max	Nm 2
	min	I <sub>bin</sub> 16
	max	I <sub>bin</sub> 18

<b>UL technical data</b>		
UL Standard		UL98

**Dimensions**

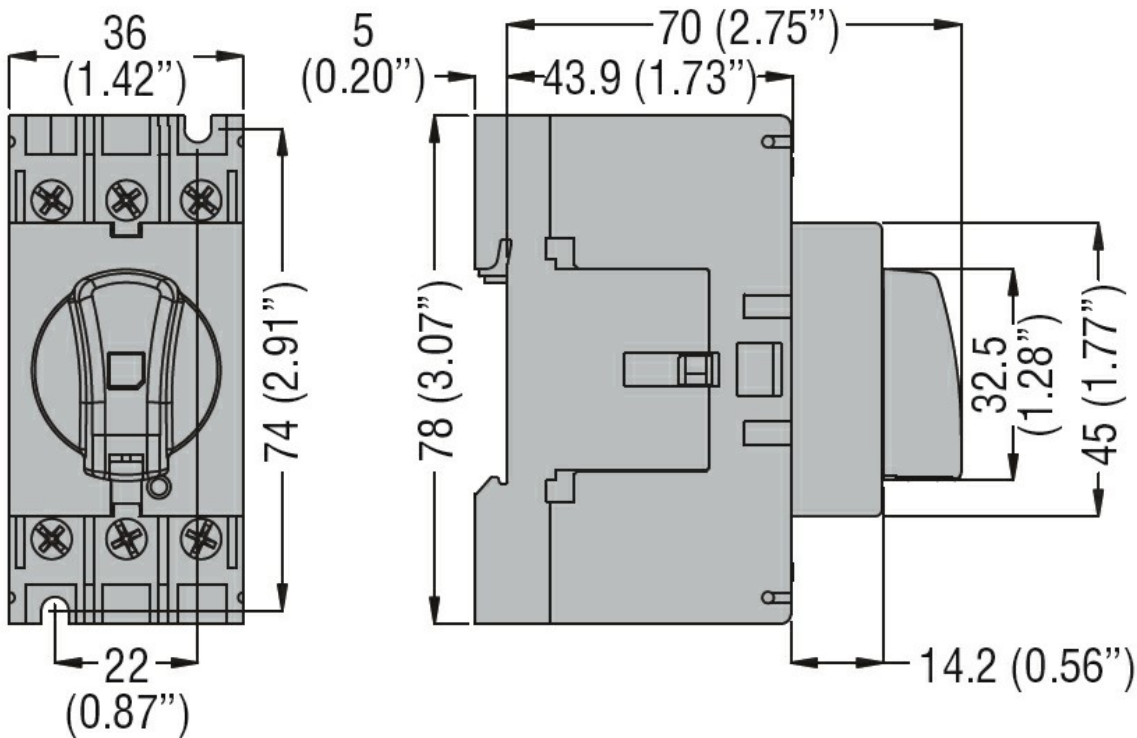

**Wiring diagrams**

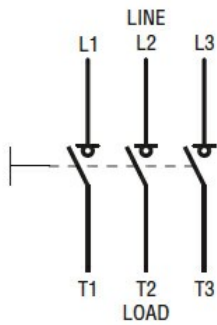

**Certifications and compliance**

Compliance

CSA C22.2 n°60947-4-1  
 IEC/EN 60947-1  
 IEC/EN 60947-3  
 UL60947-4-1

Certifications

CCC  
 CSA C22.2 n°60947-4-1  
 cULus according to UL60947-4-1  
 EAC  
 KEMA

**ETIM classification**

ETIM 8.0

EC000216 -  
 Switch  
 disconnecter