




Product designation				Neutral terminal
Product type designation				GAX3
Number of poles	Nr.			1
Operating voltage type				AC
Contact characteristics				
IEC Conventional free air thermal current I _{th}	A			63
Rated insulation voltage U _i IEC/EN	V			1000
Mechanical features				
Terminals			type	Pillar
		width	mm	5.6
		height	mm	6.5
		screw		M4
		tool		Phillips 2
Conductor section			IEC min	mm ² 0.75
			IEC max	mm ² 16
			AWG/kcmil min	18
			AWG/kcmil max	6
Weight			g	40
UL technical data				
UL Standard				UL60947-4-1
Ambient conditions				
Operating temperature			min	°C -25
			max	°C +55
Storage temperature			min	°C -40
			max	°C +70
Max altitude			m	3000
Resistance & Protection				
Frontal IP degree				IP20
Pollution degree				3
Dimensions				

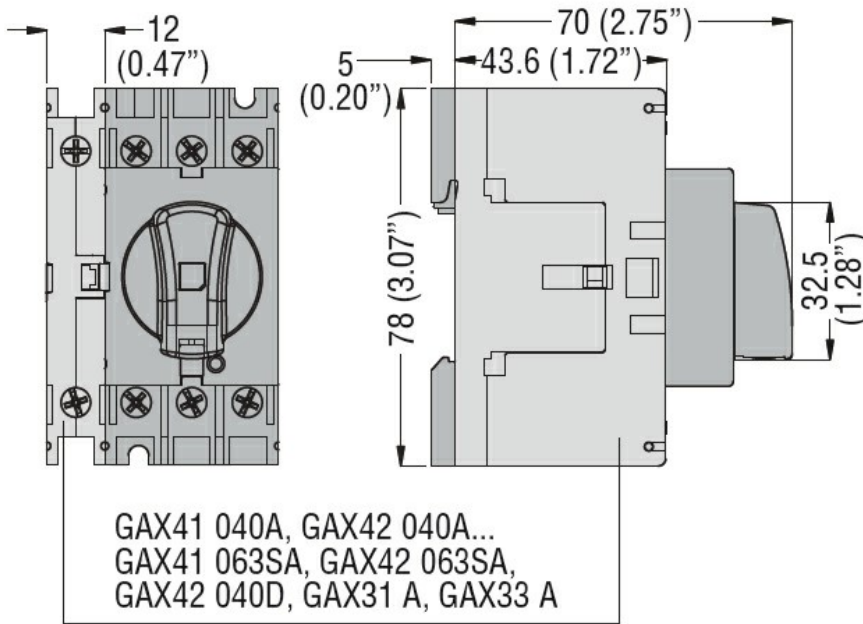

Wiring diagrams

Neutral terminal GAX31... - GAX32...



Certifications and compliance

Compliance

CSA C22.2

IEC/EN 60947-1

IEC/EN 60947-3

IEC/EN 60947-5-1

UL508

UL98

Certifications

CSA C22.2 n°14

cULus according to UL508

EAC

ETIM classification

ETIM 8.0

EC002498 -
Accessories/spare
parts for low-
voltage switch
technology