



### Mechanical features

Conductor section

Weight g 78

### UL technical data

UL Standard UL60947-4-1, UL98

### Ambient conditions

Operating temperature

|     |    |     |
|-----|----|-----|
| min | °C | -25 |
| max | °C | +55 |

Storage temperature

|     |    |     |
|-----|----|-----|
| min | °C | -40 |
| max | °C | +70 |

Max altitude


|   |      |
|---|------|
| m | 3000 |
|---|------|

### Resistance & Protection

Frontal IP degree IP65

Pollution degree 3

### Dimensions

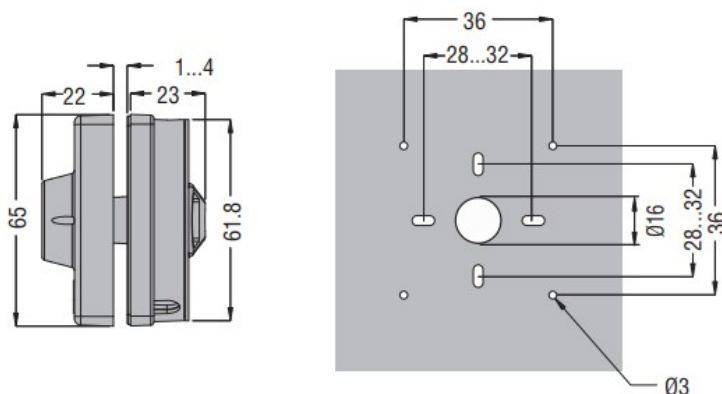

### Certifications and compliance

Compliance

CSA C22.2

IEC/EN/BS 60947-1

IEC/EN/BS 60947-3

UL 60947-4-1

UL98

Certifications

cULus

### ETIM classification

ETIM 8.0

EC000230 -  
Door coupling  
handle for  
switchgear

DOOR-COUPLING HANDLE, PADLOCKABLE. RED/YELLOW, ROTATING, FOR GA...A AND  
GA...C. SCREW FIXING. RECESSED SELECTOR. 5MM/0.2". ISO19085, IP65