



Mechanical features

Conductor section

Weight g 78

UL technical data

UL Standard UL60947-4-1,
UL98

Ambient conditions

Operating temperature

min	°C	-25
max	°C	+55

Storage temperature

min	°C	-40
max	°C	+70

Max altitude


m	3000
---	------

Resistance & Protection

Frontal IP degree IP65

Pollution degree 3

Dimensions

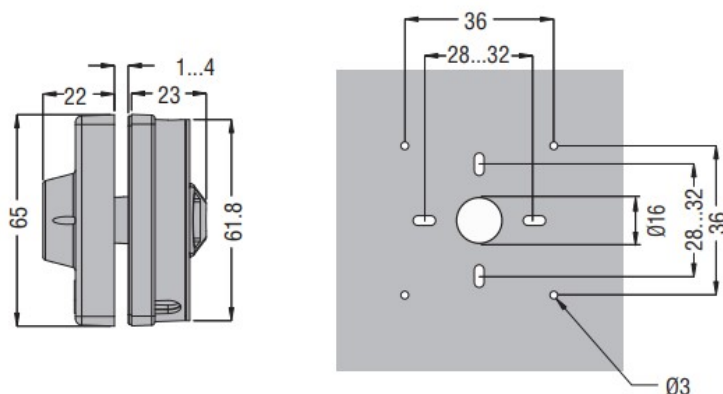

Certifications and compliance

Compliance

CSA C22.2

IEC/EN/BS 60947-1

IEC/EN/BS 60947-3

UL 60947-4-1

UL98

Certifications

cULus

ETIM classification

ETIM 8.0

EC000230 -
Door coupling
handle for
switchgear

DOOR-COUPLING HANDLE, PADLOCKABLE. BLACK, ROTATING, FOR GA...A AND GA...C.
SCREW FIXING. RECESSED SELECTOR. 5MM/0.2". ISO19085, IP65