



Mechanical features

Conductor section

Weight g 78

UL technical data

UL Standard UL60947-4-1,
UL98

Ambient conditions

Operating temperature

min	°C	-25
max	°C	+55

Storage temperature

min	°C	-40
max	°C	+70


Max altitude	m	3000
--------------	---	------

Resistance & Protection

Frontal IP degree	IP65
-------------------	------

Pollution degree	3
------------------	---

Dimensions

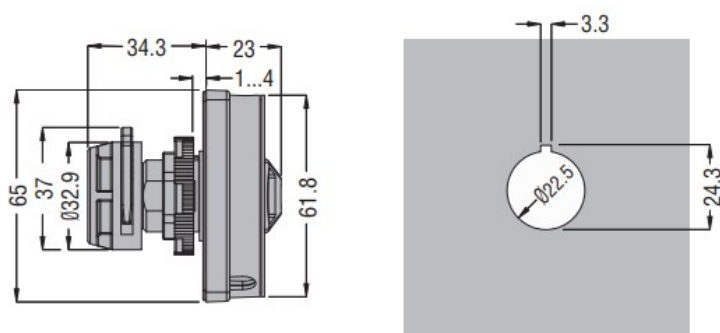

Certifications and compliance

Compliance

CSA C22.2
IEC/EN/BS 60947-1
IEC/EN/BS 60947-3
UL 60947-4-1
UL98

Certifications

cULus

ETIM classification

ETIM 8.0

EC000230 -
Door coupling
handle for
switchgear