



Mechanical features

Conductor section

Weight g 73

UL technical data

UL Standard UL60947-4-1,
UL98

Ambient conditions

Operating temperature

min	°C	-25
max	°C	+55

Storage temperature

min	°C	-40
max	°C	+70

Max altitude

m 3000

Resistance & Protection


Frontal IP degree

IP65

Pollution degree

3

Dimensions

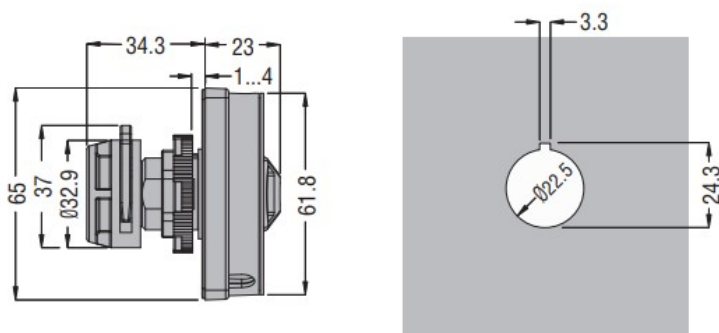

Certifications and compliance

Compliance

CSA C22.2

IEC/EN/BS 60947-1

IEC/EN/BS 60947-3

UL 60947-4-1

UL98

Certifications

cULus

ETIM classification

ETIM 8.0

EC000230 -
Door coupling
handle for
switchgear