




Dimensioni


Shaft extensions for door coupling handles

GAX7...

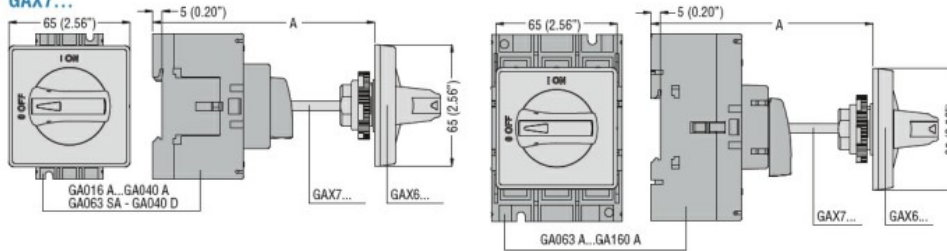

| Extension | Length [mm (in)] | A [mm (in)] maximum | | | | | |
|-----------|------------------------|---------------------|-----------------|-----------------|-----------------|-----------------|-------------------|
| | | Type of handle | | | | | |
| | | GAX61... | GAX62... | GAX63... | GAX64... | GAX67 B | GAX68... |
| GAX7055 | 55 (2.16") | 99 (3.90") | 97 (3.82") | 102 (4.01") | 116 (4.57") | 97 (3.82") | 98.5 (3.88") |
| GAX7070 | 70 (2.75") | 114 (4.49") | 112 (4.41") | 117 (4.61") | 131 (5.16") | 112 (4.41") | 113.5 (4.47") |
| GAX7090 | 90 (3.54") | 134 (5.27") | 132 (5.20") | 137 (5.39") | 151 (5.94") | 132 (5.20") | 133.5 (5.25") |
| GAX7150 | 150 (5.90") | 194 (7.64") | 192 (7.56") | 197 (7.75") | 211 (8.31") | 192 (7.56") | 193.5 (7.62") |
| GAX7200 | 200 (7.87") | 244 (9.61") | 242 (9.53") | 247 (9.72") | 261 (10.27") | 242 (9.53") | 243.5 (9.59") |
| GAX7300 | 300 (11.81") | 344 (13.54") | 342 (13.46") | 347 (13.66") | 361 (14.21") | 342 (13.46") | 343.5 (13.52") |
| GAX7400 | 400 (15.75") | 444 (17.48") | 442 (17.40") | 447 (17.60") | 461 (18.15") | 442 (17.40") | 443.5 (17.46") |
| GAX7500 | 500 (19.68") | 544 (21.42") | 542 (21.34") | 547 (21.53") | 561 (22.09") | 542 (21.34") | 543.5 (21.40") |

GAX7... used with GAX50 00, GAX50 01 and GAX60 00

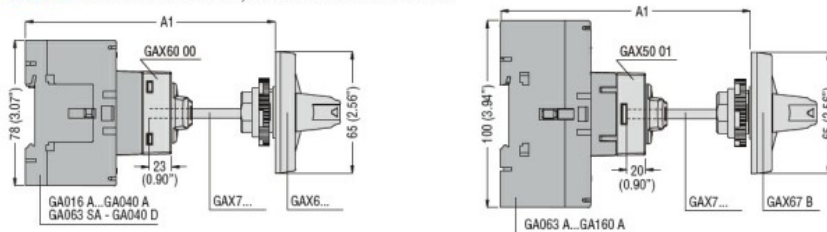

| Extension | Length [mm (in)] | A1 [mm (in)] maximum | | | | | |
|-----------|------------------------|-----------------------|-----------------|--------------------------------|-----------------|-------------------|-----------------|
| | | Used with GAX50 00 | | Used with GAX50 00/GAX50 01 | | | |
| | | GAX61... | GAX62... | GAX63... | GAX64... | GAX68... | |
| GAX7055 | 55 (2.16") | 116 (4.57") | 114 (4.49") | 119 (4.68") | 133 (5.24") | 115.5 (4.55") | 114 (4.49") |
| GAX7070 | 70 (2.75") | 131 (5.16") | 129 (5.08") | 134 (5.27") | 148 (5.83") | 130.5 (5.14") | 129 (5.08") |
| GAX7090 | 90 (3.54") | 151 (5.94") | 149 (5.87") | 154 (6.06") | 168 (6.61") | 150.5 (5.92") | 149 (5.87") |
| GAX7150 | 150 (5.90") | 211 (8.31") | 209 (8.23") | 214 (8.42") | 228 (8.98") | 210.5 (8.29") | 209 (8.23") |
| GAX7200 | 200 (7.87") | 261 (10.27") | 259 (10.20") | 264 (10.39") | 278 (10.94") | 260.5 (10.25") | 259 (10.20") |
| GAX7300 | 300 (11.81") | 361 (14.21") | 359 (14.13") | 364 (14.33") | 378 (14.88") | 360.5 (14.20") | 359 (14.13") |
| GAX7400 | 400 (15.75") | 461 (18.15") | 459 (18.07") | 464 (18.27") | 468 (18.42") | 460.5 (18.13") | 459 (18.07") |
| GAX7500 | 500 (19.68") | 561 (22.09") | 559 (22.01") | 564 (22.20") | 578 (22.75") | 560.5 (22.07") | 559 (22.01") |

Omologazioni e conformità

Omologazioni

CSA C22.2

IEC/EN 60947-1

IEC/EN 60947-3

UL508

UL98

Certificazioni

CCC

cULus according to UL508 / CSA C22.2 n°14

cULus according to UL98 / CSA C22.2 n°4

EAC

Classificazione ETIM

ETIM 8.0

EC002498 -
Accessori per
dispositivi di
commutazione
bassa tensione