



Mains choke for VLB3 variable speed drives VLBXL140 200A, 0.14mH, for VLB3 size 90...110kW

Product designation

Product type designation

Version

**General characteristics**

Rated output current	A	200
Rated output power	kW	90...110


**Ambient conditions**


Temperature	Operating temperature		
	min	°C	-10
	max	°C	+55

**Housing**


Weight	Kg	32
--------	----	----

**Dimensions**

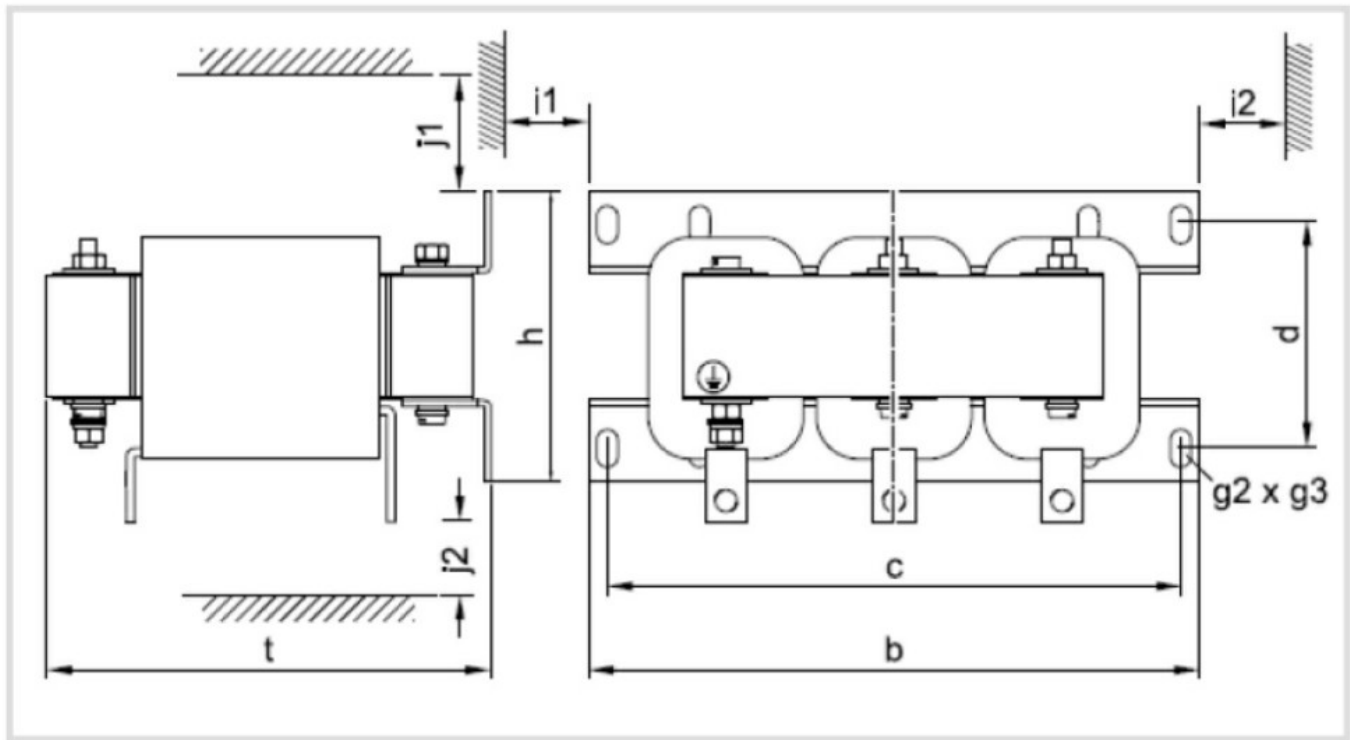

	b	h	t	c	d	g2 x g3	i1,i2	j1, j2	
	[mm]								
VLBX L330	267	115	205	249	78.5	7 x 13	30	100	11.5
VLBX L300	267	139	205	249	102.5				16.5
VLBX L190	291	149	215	273	116.5	22.5			
VLBX L140	352	144	265	328	103.5	10 x 16			25.0

Wiring diagrams

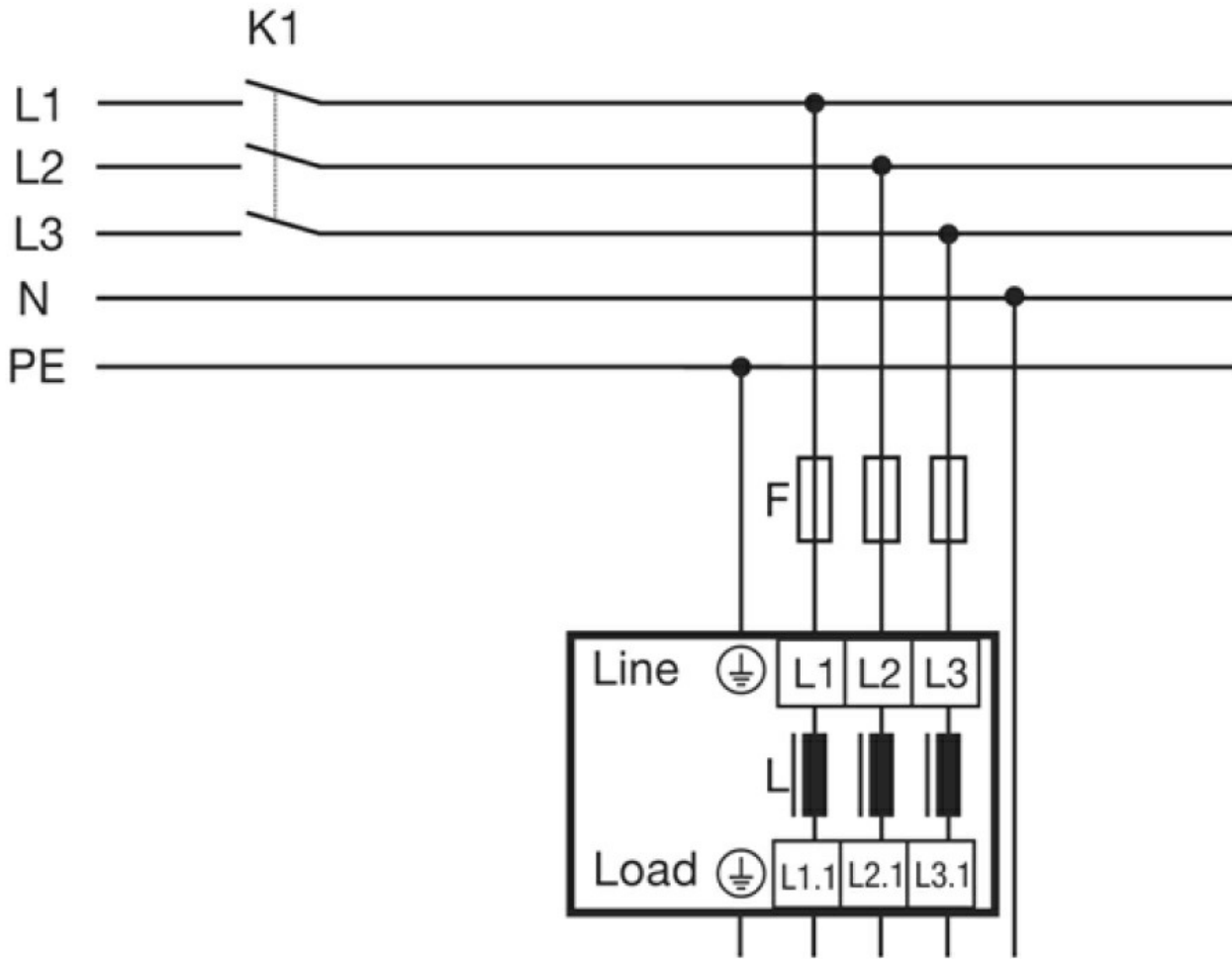

### Certifications and compliance

Compliance

IEC/EN/BS 61558-1

### ETIM classification

ETIM 8.0

EC002565 -  
Filter circuit coil  
for low-voltage