



Mains choke for  
 VLB3 variable  
 speed drives  
 VLBXL190  
 160A, 0.19mH,  
 for VLB3 size  
 75kW

Product designation

Product type designation

Version

**General characteristics**

Rated output current	A	160
Rated output power	kW	75

**Ambient conditions**

Temperature


Operating temperature


min	°C	-10
max	°C	+55

**Housing**


Weight	Kg	26
--------	----	----

**Dimensions**

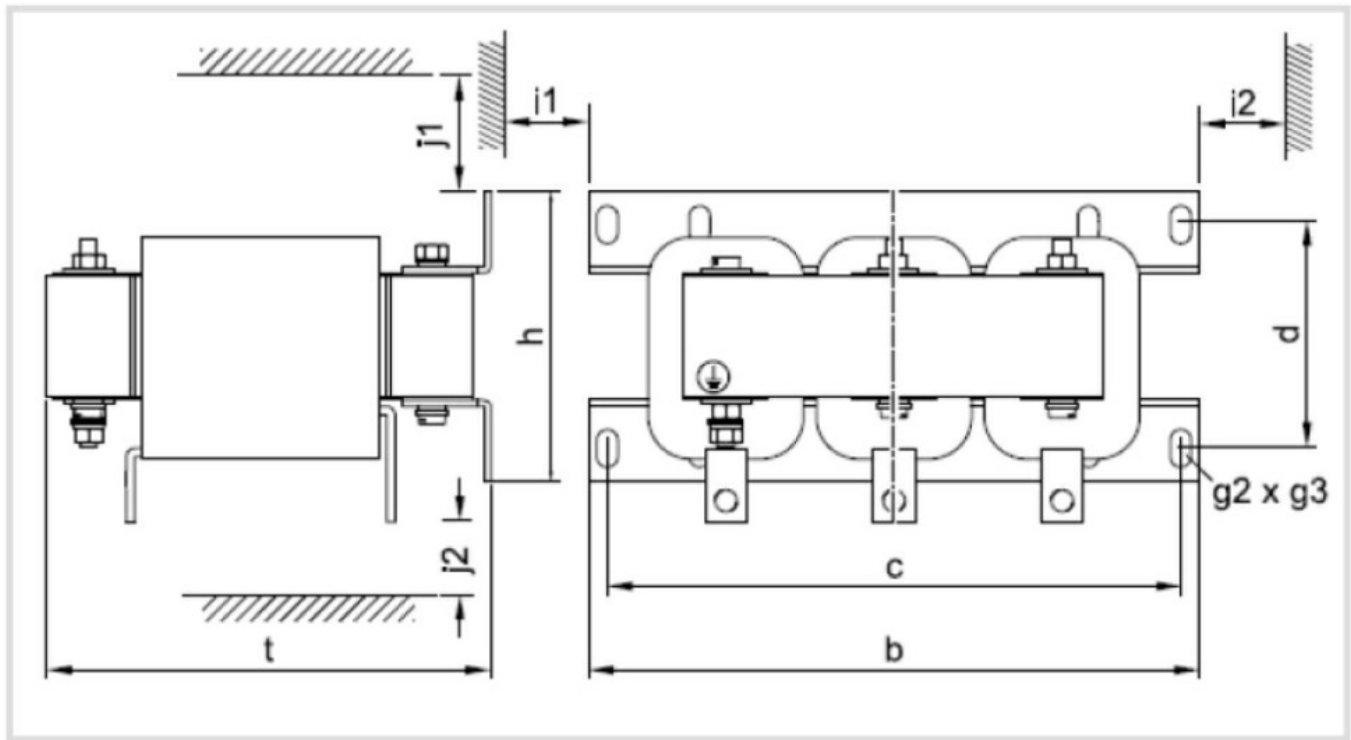

	b	h	t	c	d	g2 x g3	i1,i2	j1, j2	
	[mm]								[kg]
VLBX L330	267	115	205	249	78.5	7 x 13	30	100	11.5
VLBX L300	267	139	205	249	102.5				16.5
VLBX L190	291	149	215	273	116.5	22.5			
VLBX L140	352	144	265	328	103.5	10 x 16			25.0

Wiring diagrams

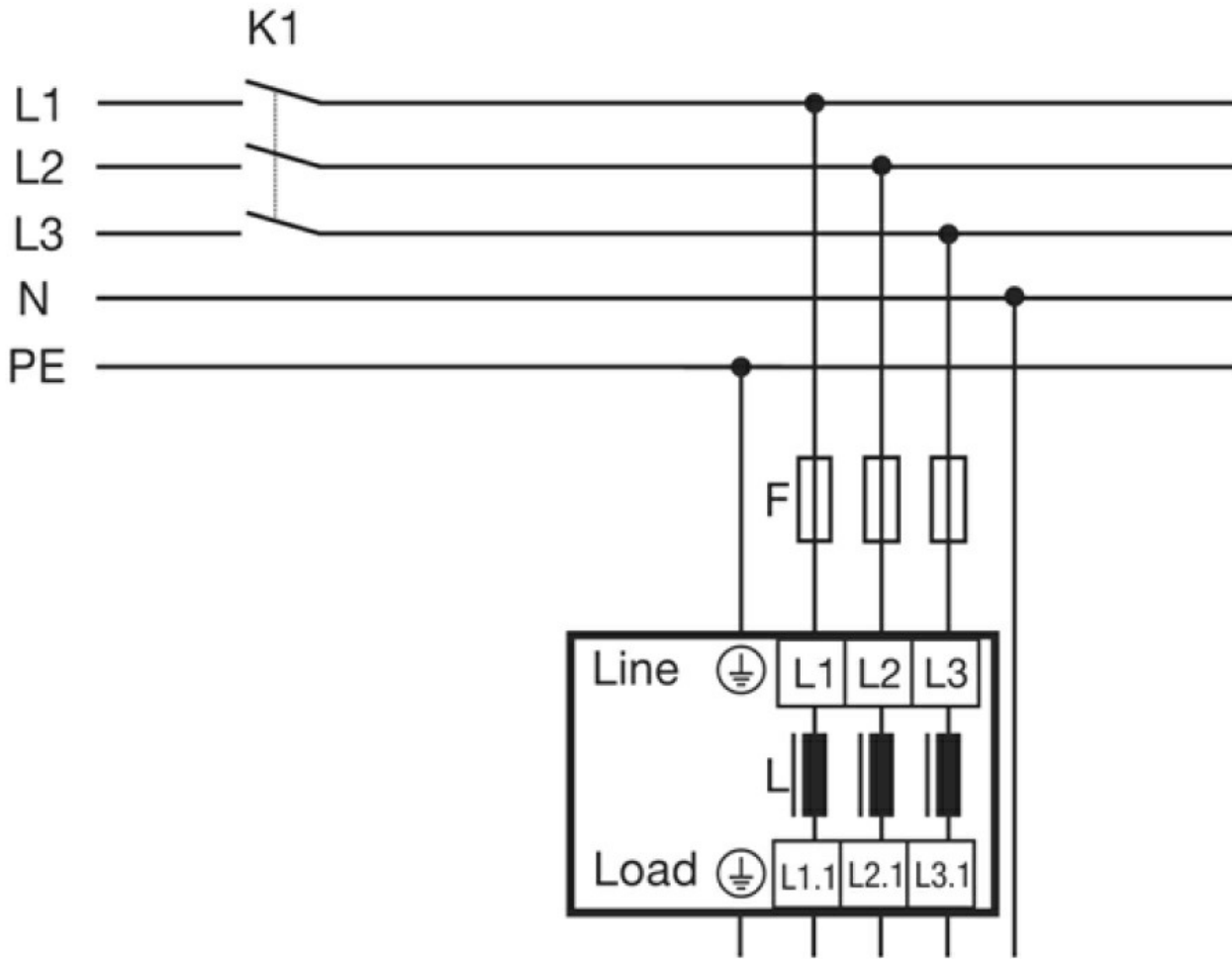

**Certifications and compliance**

Compliance

IEC/EN/BS 61558-1

**ETIM classification**

ETIM 8.0

EC002565 -  
 Filter circuit coil  
 for low-voltage