



Mains choke for
 VLB3 variable
 speed drives
 VLBXL330
 90A, 0.33mH, for
 VLB3 size 45kW

Product designation

Product type designation

Version

General characteristics

Rated output current	A	90
Rated output power	kW	45


Ambient conditions


Temperature				
	Operating temperature			
		min	°C	-10
		max	°C	+55

Housing


Weight	Kg	16
--------	----	----

Dimensions

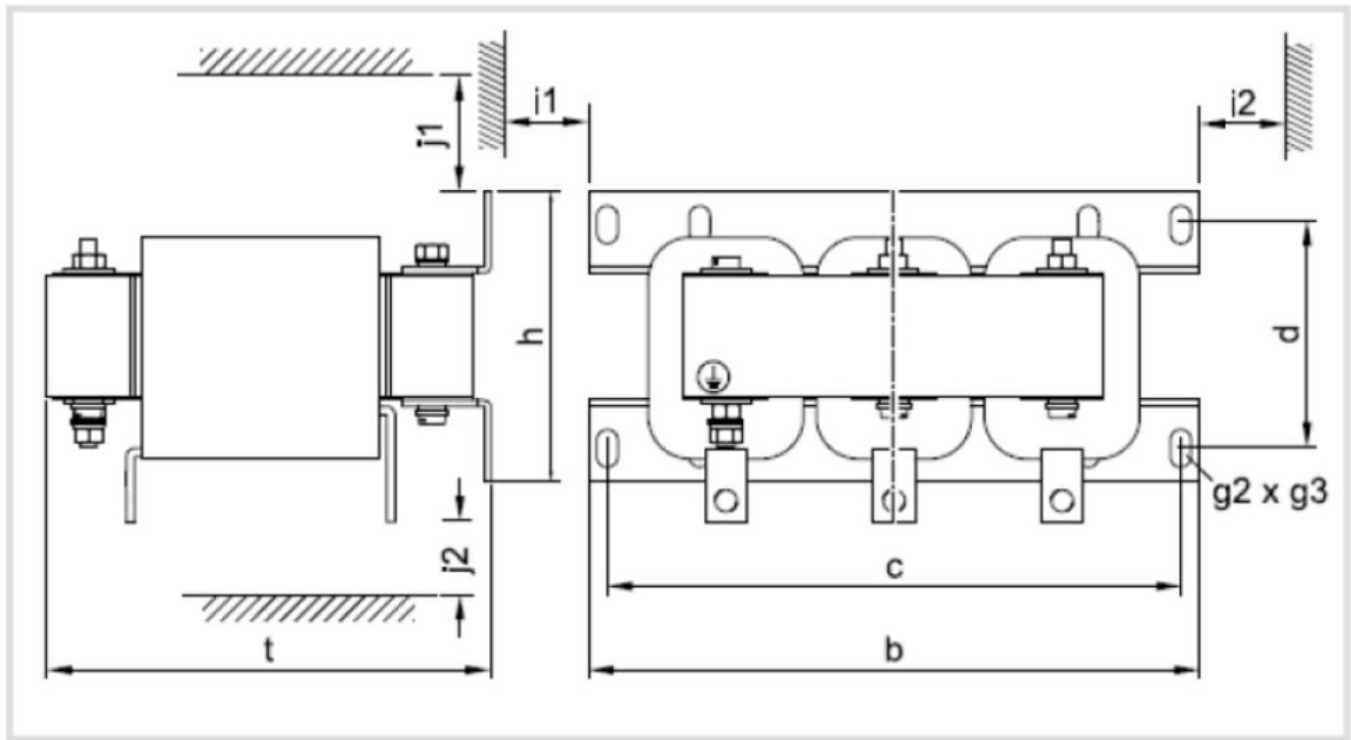

	b	h	t	c	d	g2 x g3	i1,i2	j1, j2	
	[mm]								[kg]
VLBX L330	267	115	205	249	78.5	7 x 13	30	100	11.5
VLBX L300	267	139	205	249	102.5				16.5
VLBX L190	291	149	215	273	116.5	22.5			
VLBX L140	352	144	265	328	103.5	10 x 16			25.0

Wiring diagrams

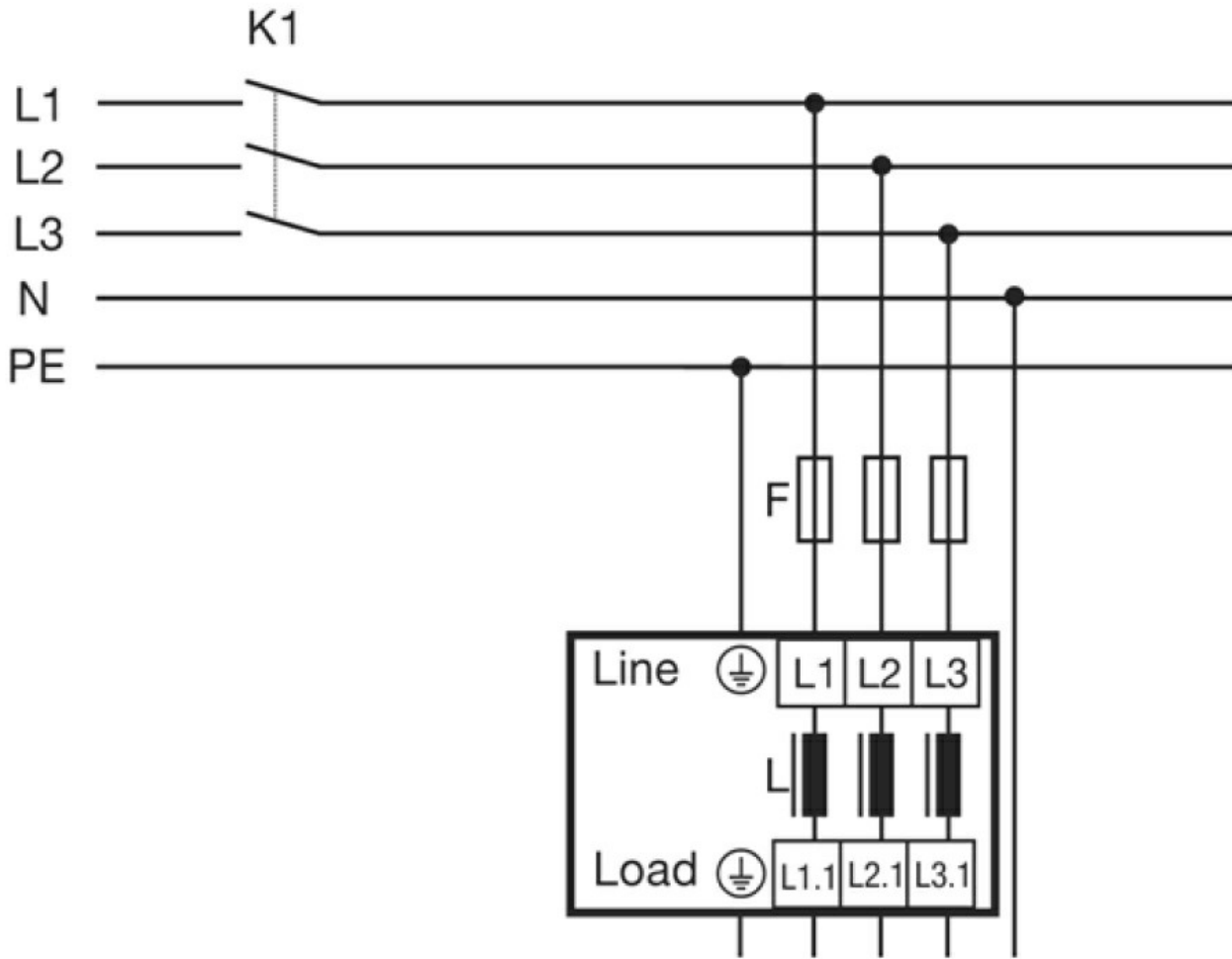

Certifications and compliance

Compliance

IEC/EN/BS 61558-1

ETIM classification

ETIM 8.0

EC002565 -
 Filter circuit coil
 for low-voltage