



Mains choke for  
 VLB3 variable  
 speed drives  
 VLBXL370  
 80A, 0.37mH, for  
 VLB3 size 37kW

Product designation

Product type designation

Version

**General characteristics**

Rated output current	A	80
Rated output power	kW	37

**Ambient conditions**

Temperature


Operating temperature


min	°C	-10
max	°C	+55

**Housing**


Weight	Kg	12.5
--------	----	------

**Dimensions**

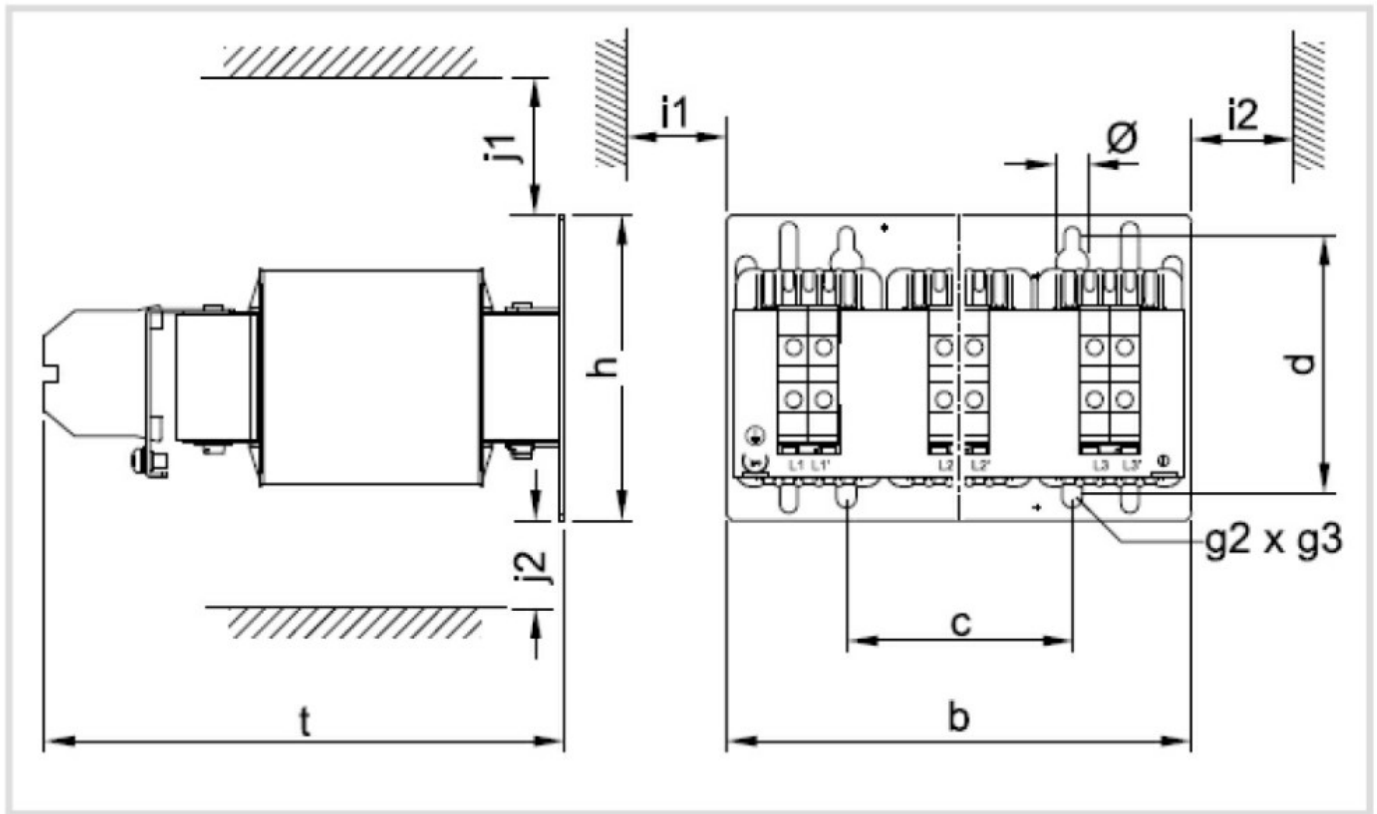

	b	h	t	c	d	$g2 \times g3$ $\varnothing$	$i1, i2$	$j1, j2$	
	[mm]								
VLBX L590	185	112	210	90	93	8 x 12	30	75	8.35
VLBX L370	210	125	240	105	106	13			12.5

Wiring diagrams

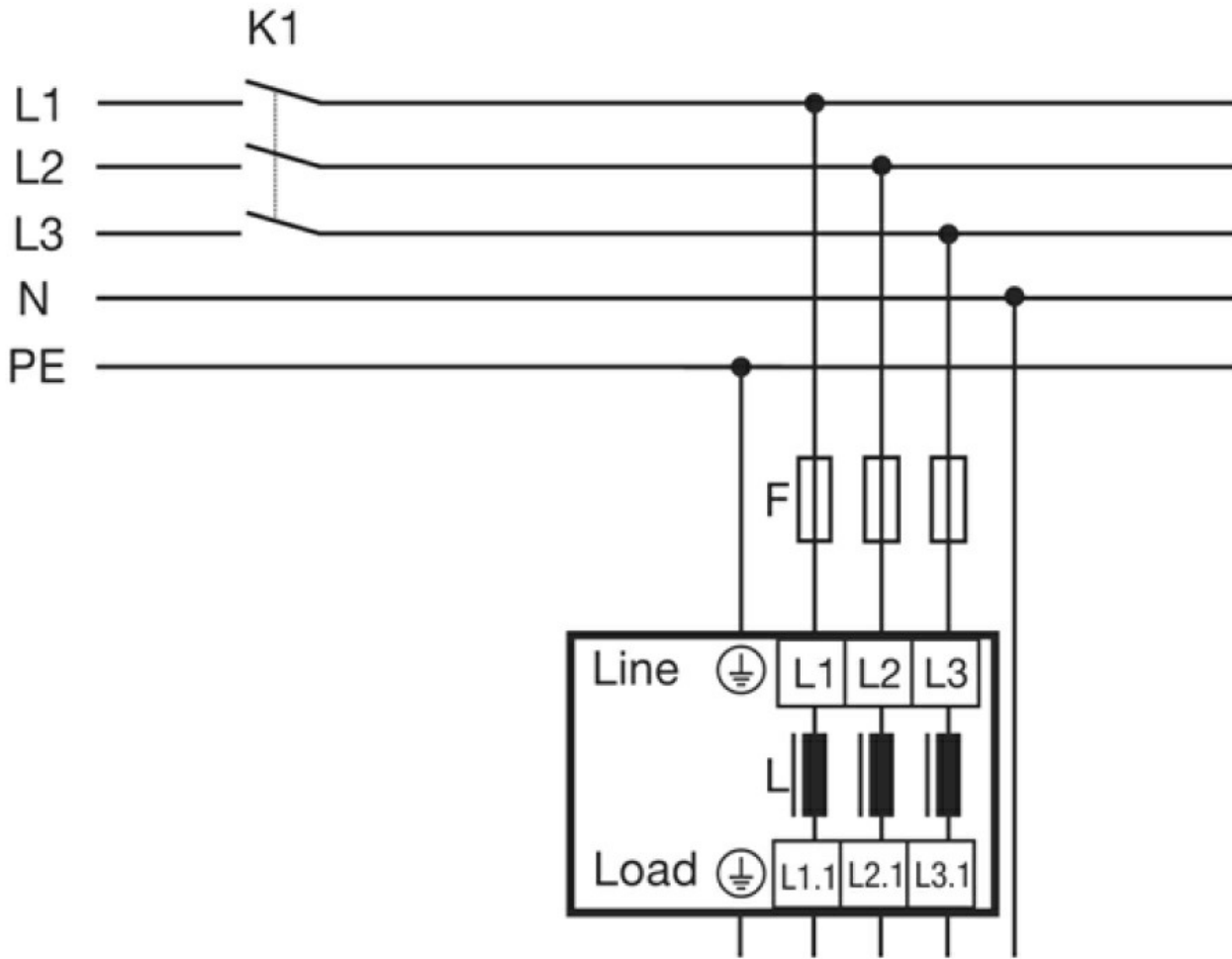

**Certifications and compliance**

Compliance

IEC/EN/BS 61558-1

**ETIM classification**

ETIM 8.0

EC002565 -  
 Filter circuit coil  
 for low-voltage